


Brass Pipe Fittings
90° Female Pipe Elbow (FPT)

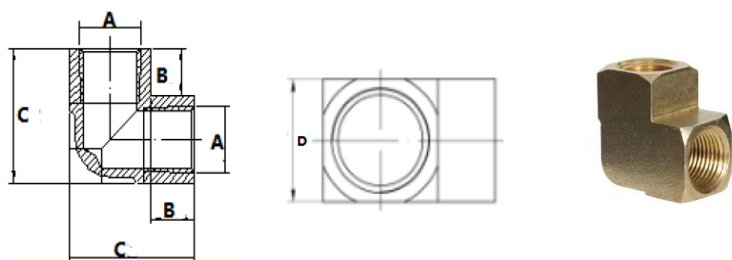

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: FPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
23500X4	1/4	1/4"	0.37"	1.06"	11/16"
23500X6	3/8	3/8"	0.39"	1.20"	13/16"
23500X8	1/2	1/2"	0.49"	1.48"	1"
23500X12	3/4	3/4"	0.51"	1.77"	1-1/4"

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov