


Brass Pipe Fittings
Street Tee (MPT x FPT)

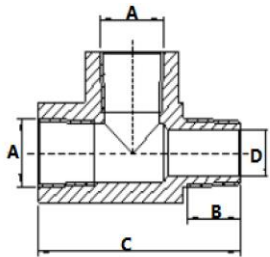

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT x FPT x FPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
23750X2	1/8"	1/8"	0.35"	1.20"	0.21"
23750X4	1/4"	1/4"	0.44"	1.69"	0.35"
23750X6	3/8"	3/8"	0.57"	1.81"	0.43"
23750X8	1/2"	1/2"	0.75"	2.32"	0.59"
23750X12	3/4"	3/4"	0.75"	2.52"	0.75"

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov