


Brass Compression Fittings
Union (OD Tube x OD Tube)

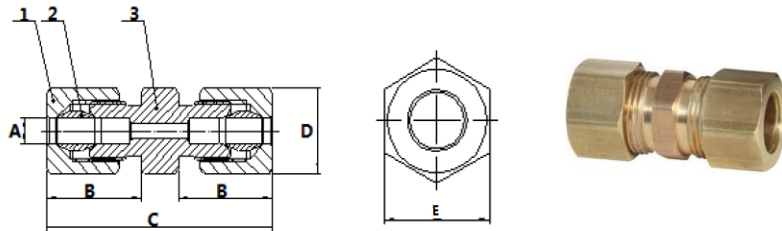

Use with Copper, Brass, Aluminum or Plastic Tubing
(Plastic Tubing Requires Tubing Insert 295)
Three piece construction: Nut ,Sleeve (or Ferrule) and Body
Meets SAE, ASA and ASME Specifications and Standards
Connection: OD Tube x OD Tube
Pressure Rating 500 PSI
Temperature Range: -65°F to 250°F

Part No.	Size (In)	A(In)	B(In)	C(In)	D(In)	E(In)
262X4X4	1/4 x 1/4	1/4"	0.33"	0.87"	7/16-24UN	7/16"
262X6X6	3/8 x 3/8	3/8"	0.35"	0.94"	9/16-24UN	9/16"
262X8X8	1/2 x 1/2	1/2"	0.45"	1.12"	11/16-24UN	11/16"

Part No.	Description	Material
1	Nut	Brass
2	Sleeve	Brass
3	Body	Brass

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov