


Brass Compression Fittings
Branch Tees (OD Tube x OD Tube x MPT)

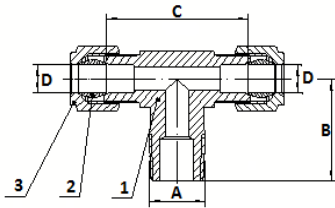

Use with Copper, Brass, Aluminum or Plastic Tubing
(Plastic Tubing Requires Tubing Insert 295)
Three Piece onstruction: Nut, Sleeve (or Ferrule) and Body
Meets SAE, ASA and ASME Specifications and Standards
Connection: ODTube x OD Tube x MPT
Pressure Rating 500 PSI
Temperature Range: -65°F to 250°F

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
263X4TX4TX2M	1/4 OD Tube (2) x 1/8 MPT	1/8"	1.16"	1.38"	7/16-24UN
263X4TX4TX4M	1/4 OD Tube (2) x 1/4 MPT	1/4"	1.16"	1.38"	7/16-24UN
263X6TX6TX6M	3/8 OD Tube (2) x 3/8 MPT	3/8"	1.16"	1.81"	9/16-24UN
263X8TX8TX4M	1/2 OD Tube (2) x 1/4 MPT	1/4"	1.28"	1.89"	11/16-24UN
263X8TX8TX8M	1/2 OD Tube (2) x 1/2 MPT	1/2"	1.35"	1.89"	11/16-24UN

Part No.	Description	Material
1	Nut	Brass
2	Sleeve	Brass
3	Body	Brass

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov