


Brass Compression Fittings
90° Female Elbow (OD Tube x FPT)

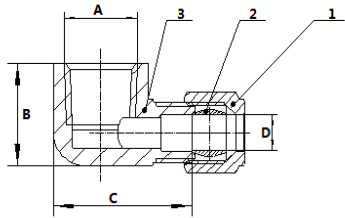

Use with Copper, Brass, Aluminum or Plastic Tubing
(Plastic Tubing Requires Tubing Insert 295)
Three Piece Construction: Nut, Sleeve (or Ferrule) and Body
Meets SAE, ASA and ASME Specifications and Standards
Connection: OD Tube x FPT
Pressure Rating 500 PSI
Temperature Range: -65°F to 250°F

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
269FX4X2	1/4 x 1/8	1/8"	0.73"	1.06"	7/16-24UN
269FX4X4	1/4 x 1/4	1/4"	0.73"	1.06"	7/16-24UN
270X4X4*	1/4 x 1/4*	1/4"	1.20"	1.29"	1/4" O.D.
269FX6X4	3/8 x 1/4	1/4"	0.94"	1.18"	9/16-24UN
269FX6X6	3/8 x 3/8	3/8"	0.94"	1.29"	9/16-24UN
269FX8X4	1/2 x 1/4	1/4"	1.04"	1.37"	11/16-24UN
269FX8X8	1/2 x 1/2	1/2"	1.11"	1.61"	11/16-24UN
269FX12X8	3/4 x 1/2	1/2"	1.11"	1.65"	1-18UN
269FX12X12	3/4 x 3/4	3/4"	1.51"	1.93"	1-18UN

* with captive sleeve nut

Part No.	Description	Material
1	Nut	Brass
2	Sleeve	Brass
3	Body	Brass

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov