


Brass Compression Fittings
90° Male Elbow (OD Tube x MPT)

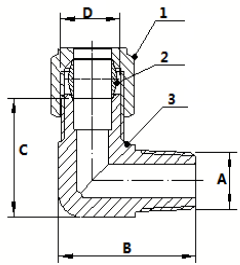

Use with Copper, Brass, Aluminum or Plastic Tubing

(Plastic Tubing Requires Tubing Insert 295)

Three Piece Construction: Nut, Sleeve (or Ferrule) and Body

Meets SAE, ASA and ASME Specifications and Standards

Connection: OD Tube x MPT

Pressure Rating 500 PSI

Temperature Range: -65°F to 250°F

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
269X4X2	1/4 x 1/8	1/8"	0.94"	0.81	7/16-24UN
269X4X4	1/4 x 1/4	1/4"	1"	0.87"	7/16-24UN
269X6X4	3/8 x 1/4	1/4"	1.12"	0.96"	9/16-24UN
269X6X6	3/8 x 3/8	3/8"	1.24"	1.12"	9/16-24UN
269X6X8	3/8 x 1/2	1/2"	1.46"	1.28"	9/16-24UN
269X8X4	1/2 x 1/4	1/4"	1.46"	1.32"	11/16-24UN
269X8X6	1/2 x 3/8	3/8"	1.46"	1.32"	11/16-24UN
269X8X8	1/2 x 1/2	1/2"	1.46"	1.32"	11/16-24UN
269X12X8	3/4 x 1/2	1/2"	1.93"	1.75"	1-18UN
269X12X12	3/4 x 3/4	3/4"	1.93"	1.75"	1-18UN

Part No.	Description	Material
1	Nut	Brass
2	Sleeve	Brass
3	Body	Brass

Drawing Date: 8/2019

Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov