


Brass Pipe Fittings
Slotted-Head Plug (MPT)

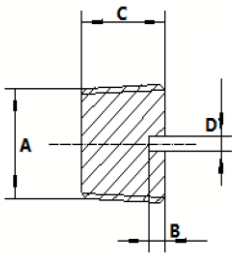

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
281X2	1/8	1/8"	0.06"	0.31"	0.05"
281X4	1/4	1/4"	0.08"	0.42"	0.08"
281X6	3/8	3/8"	0.09"	0.43"	0.09"

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov