

ABS Dry Pressure and Vacuum Gauges

ABS Plastic

Ideal for Use In:

**Moist Areas and Applications Where
Stainless Steel Was Used to
Avoid Rusting**

Features

- ABS Impact and Corrosion Resistant Case
- Available with Rubber Gauge Covers for Additional Protection from Rugged Environments and Impact
- Meets ASME B40.1 Standards

Stocked

- 160, 200, 300 PSI
- 2" Dial
- Center Back Mount or Lower Mount
- Packaged in a Plain White Box or Packaged for Retail

Available as Special Order

- 1-1/2", 2-1/2" or 3-1/2" Dials
- Acrylic or Glass Lens
- See Chart for Other PSI options



Lower Mount





Back Mount



Gauge with Cover

Specifications

Dial Size	1.5", 2", 2.5" and 3.5"
Case	ABS Corrosion Resistant Plastic
Standards	ASME B40.1
Lens	Acrylic, Glass or Polycarbonate
Ambient Temperature	-40F° to 150° F
Bourdon Tube	Bronze
Socket	Brass
Accuracy	± 3-2-3
Connections	1-1/2" Dials 1/8"NPT, All Other Sizes are 1/4"NPT
Ranges PSI/kPa	0-30"Hg, 15,30,60,100,160,200,300,400,600,1000,2000,3000, 4000,5000 and 6000 psi

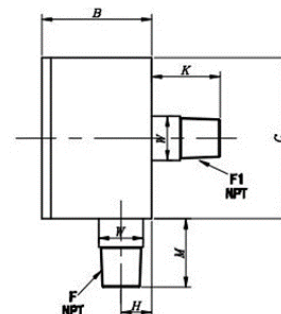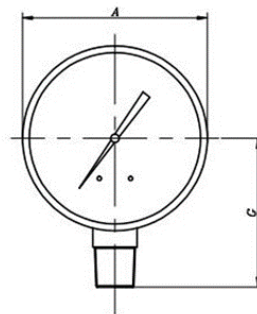

Midwest Control
1101 Brown St
Wauconda IL 60084
Phone: (847) 487-5599
Fax: (847) 487-09009
Email: order@midwest-control.com
www.midwest-control.com

Dial Size	A		B		C	F & F1	G	H	K	M	W	
	Lower Mount	Back Mount	Lower Mount	Back Mount							Lower Mount	Back Mount
1.5"	1.63	1.63	.90	.93	1.61	1/8"	1.48	.33	.63	.68	.43	.43
2.0"	2.11	2.11	1.06	1.04	2.09	1/4"	1.77	.36	.73	.72	.54	.54
2.5"	2.51	2.51	1.14	1.13	2.48	1/4"	2.00	.43	.70	.71	.54	.54
3.5"	3.46	3.46	1.19	1.20	3.43	1.4"	2.70	.40	.70	.98	.54	.54