


AM-PLUG Aluminum Manifold Plug

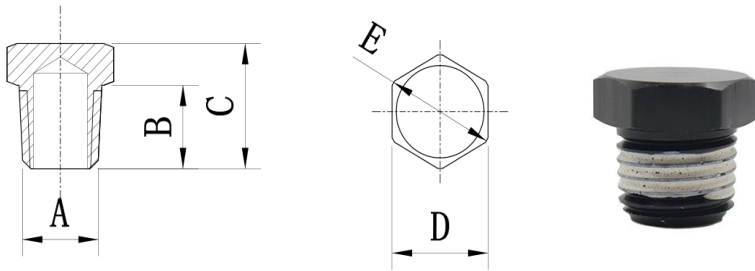

Aluminum Black anodizing
With Pre-applied Thread Sealant
Rated for 1000 PSI Air, 300 PSI Non Shock Hydraulic @72°F
Temperature Range: -10°F to 200°F

Part No.	A (In)	B (In)	C (In)	D (In)	E (In)	Carton Qty.	Wt.(lbs.)
AM-PLUG18	1/8"	0.37"	0.55"	7/16"	0.60	1000	0.0086
AM-PLUG25	1/4"	0.47"	0.67"	9/16"	0.77	1000	0.0146
AM-PLUG38	3/8"	0.53"	0.75"	11/16"	0.94	1000	0.0247

Drawing Date:7/2020
Rev Level-Date: R1 11/2020