


BABC-DK Strainer with Self-Cleaning Valve and Drain Hose Kit



Self Cleaning Drain/Lever
Lever Horizontal Position: Closed
Lever Vertical Position: Open

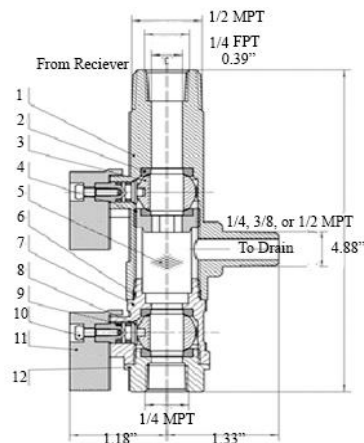

600 PSI CWP Service
Temperature Range: -4 F to 200 F
Forged Brass Construction
Blow Out Proof Stem
PTFE and Rubber Seals
Hose Connection (Strainer Discharge): 1/4" FPT
Connection to Condensate Drain : 1/4", 3/8" or 1/2" MPT
Receiver Connection (Strainer Inlet): 1/4 " FPT and 1/2" MPT
Includes 3 Ft. Drain Hose Kit

With the self clean feature It is no longer necessary to isolate the drain from the compressed air source to clean the BPS inlet screen. The self cleaning features Includes an additional lever/ isolation valve which is typically In the closed position. Periodically the lever should be opened for a few seconds to allow compressed air from the receiver to blow by the BPS screen pushing the debris out from the screen.

BABC Strainer with Self-Cleaning Valve

Receiver/Drain

Part No.	Size	Port Size
BABC-5025	1/2 x 1/4	0.39"
BABC-5033	1/2 x 3/8	0.39"
BABC-5050	1/2 x 1/2	0.39"

BABC Strainer with Self-Cleaning Valve w/Drain Hose Kit

Receiver/Drain

Part No.	Size	Port Size
BABC-5025DK	1/2 x 1/4	0.39"
BABC-5033DK	1/2 x 3/8	0.39"
BABC-5050DK	1/2 x 1/2	0.39"

Part No.	Description	Qty	Material
1	Clean Valve Cap	1	Brass
2	Clean Valve Body	1	Brass
3	Ball Seats	4	PTFE
4	Balls	2	Cr.Brass
5	Screen	1	Stainless Steel
6	Retainer Nut	1	Brass
7	Strainer Body	1	Brass
8	Stem seals	4	Rubber
9	Stems	2	Brass
10	Handle Screw	2	Steel
11	Handles	2	Zinc Cast
12	Connection Seal	1	Rubber

Drawing Date: 5/2009
Rev. Level-Date: R1 8/2020



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov