


Brass Ball Valves

Specifications	Approvals
600 PSI CWP 150 WSP Vacuum Service Up to 29.9" Hg - Temperature Range: -20° F to 370 ° F - Connection: FNPT x FNPT - Full Port - Blow Out Proof Stem - Construction Body and Valve Cap: Brass (C3800) - Chrome-Plated Ball - Ball Seat and Packing: PTFE - Handle: Oval Chrome-Plated Steel /Vinyl Grip	- RoHs Compliant Meets - Meets MSS SP-110 Standards - ISO Registered Factory

BVO Series

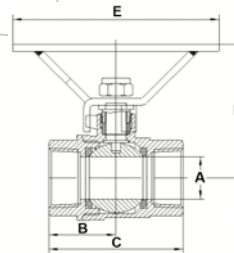


NPT	Model No.	A (In)	B (In)	C (In)	D (In)	E (In)	CV	Wt. (lbs.)	Carton Qty
1/2"	BVO-50	0.59	1.10	2.20	1.97	2.76	18.55	0.59	60
3/4"	BVO-75	0.75	1.38	2.39	2.56	2.76	29.76	0.82	48
1"	BVO-100	0.98	1.77	2.90	2.95	2.76	51.55	1.10	36



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -20° F to 370° F

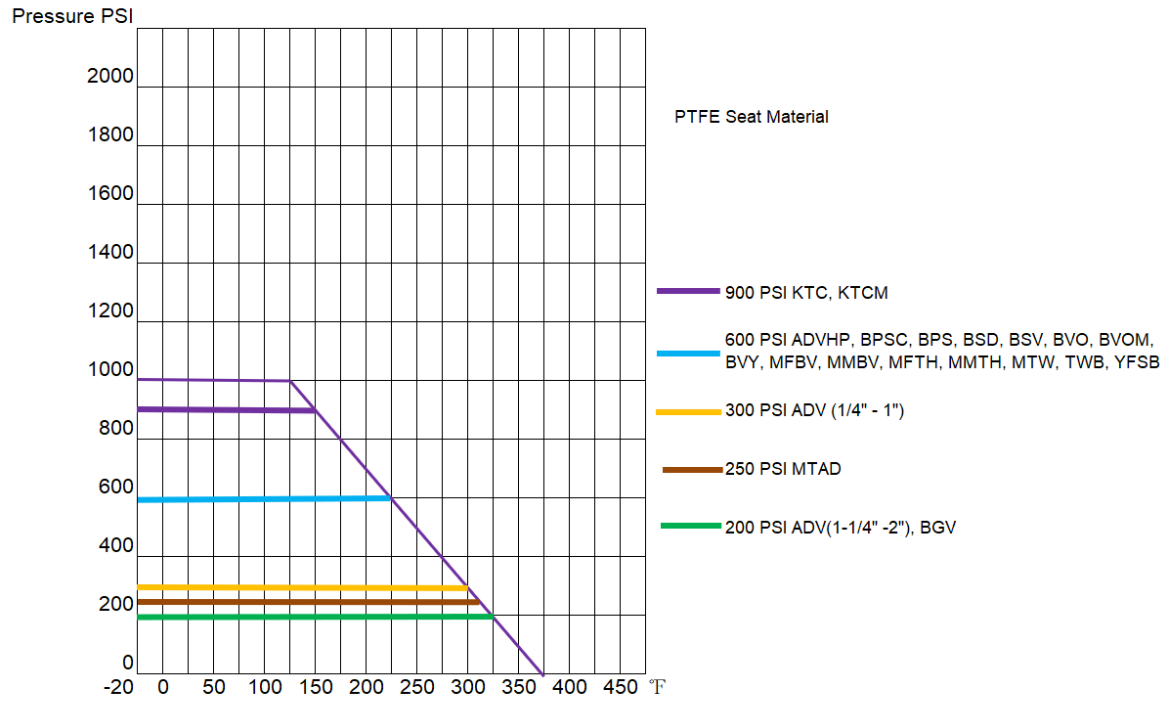

Drawing Date: 8/2022
Rev. Level-Date:

Technical Data