


Brass Ball Valves with Round Handle

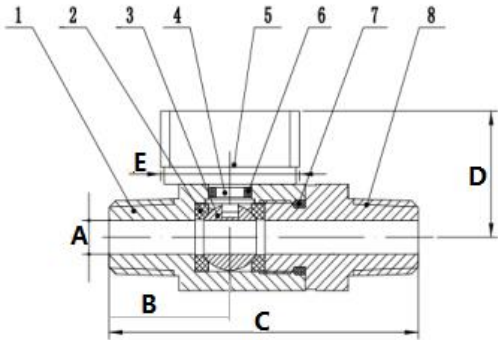

1000 PSI CWP 150 WSP
Suitable for Vacuum Service to 29.9"Hg
Full port
Temperature Range: -4°F to 370°F
2-Piece Heavy Duty Construction
Brass Body and Cap
PTFE Ball Seat
Viton® Stem Sealing
Chrome-Plated Brass Ball
Round Handle
MPT Connection
ISO Registered Factory
Meets MSS SP-110 Standards
RoHS Compliant

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Cv	Wt. (lbs.)	Carton Qty
BVRM-18M	1/8"	0.24	0.82	2.10	0.89	1.02	6.00	0.21	80
BVRM-25M	1/4"	0.24	0.88	2.26	0.89	1.02	8.23	0.24	80

Weights Are ± 3%

Part No.	Description	Material
1	Body	Brass
2	Seat	PTFE
3	Ball	Chrome-Plated Brass
4	Stem	Brass
5	Handle	Copper-Plated
6	Stem Seal	Viton®
7	Seal	Viton®
8	Cap	Brass

Drawing Date: 10/2018
Rev. Level-Date: R5 2/2023



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov