


Compression Brass Ball Valves w/Round Handle

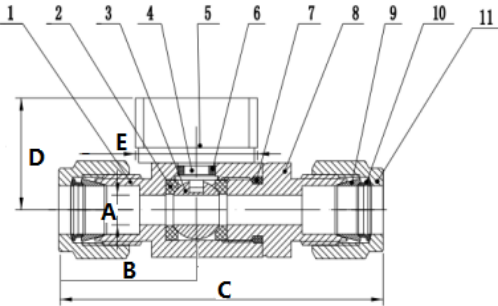

1000 PSI CWP 150 WSP
Suitable for Vacuum Service to 29.9"Hg
Full port
Temperature Range: -4°F to 370°F
2-Piece Heavy Duty Construction
Brass Body and Cap
PTFE Ball Seat
Viton® Stem Sealing
Chrome-Plated Brass Ball
Round Handle
Compression Double-Ferrule
OD Connection
ISO Registered Factory
Meets MSS SP-110 Standards
RoHS Compliant

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Cv	Wt. (lbs.)	Carton Qty
BVRM-18Y	1/8"	0.13	0.94	2.40	1.11	1.02	6.00	0.24	80
BVRM-25Y	1/4"	0.25	1.01	2.59	1.11	1.02	8.23	0.26	80
BVRM-38Y	3/8"	0.37	1.06	2.71	1.11	1.02	8.23	0.28	80

Weights Are ± 3%

Part No.		Material
1	Body	Brass
2	Seat	PTFE
3	Ball	Chrome-Plated Brass
4	Stem	Brass
5	Handle	Copper-Plated
6	Stem Seal	Viton®
7	Seal	Viton®
8	Cap	Brass
9	OD	Brass
10	OD	Brass
11	OD Nut	Brass

Drawing Date: 10/2018
Rev. Level-Date: R4 10-2022