

Carbon Steel Ball Valves


Specifications

- 2000 PSI CWP 150 WSP
Vacuum Service Up to 29.9" Hg
- Temperature Range: -20° F to 450 ° F
- Connection: FNPT x FNPT
- 1/4" - 3/8" Full Port
1/2" Regular Port
3/4" - 1" Reduced Port
- Blow Out Proof Stem
- Construction (Body and Valve Cap):
2-Piece Carbon Steel 1/4" - 3/8"
1-Piece Carbon Steel 1/2" - 1"
- 304 Stainless Steel Ball and Stem
- Ball Seat and Seals: RPTFE
- Handle: 201 Stainless Steel / Vinyl Grip

Approvals

- RoHs Compliant Meets
- Meets MSS SP-110 Standards
- ISO Registered Factory

CSV Series

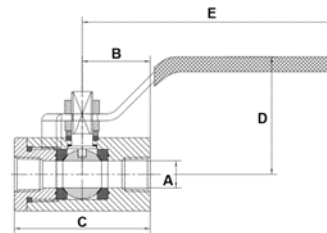


NPT	Model No.	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/4"	CSV-25	0.37	1.18	2.36	1.63	4.02	8.23	0.63	30
3/8"	CSV-38	0.37	1.18	2.36	1.63	4.02	8.23	0.59	30
1/2"	CSV-50	0.37	1.18	2.36	2.07	4.54	15.00	0.73	30
3/4"	CSV-75	0.49	1.32	2.64	2.36	4.54	10.00	1.03	24
1"	CSV-100	0.66	1.44	2.87	2.52	5.31	16.00	1.46	24



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -20 °F to 450 °F

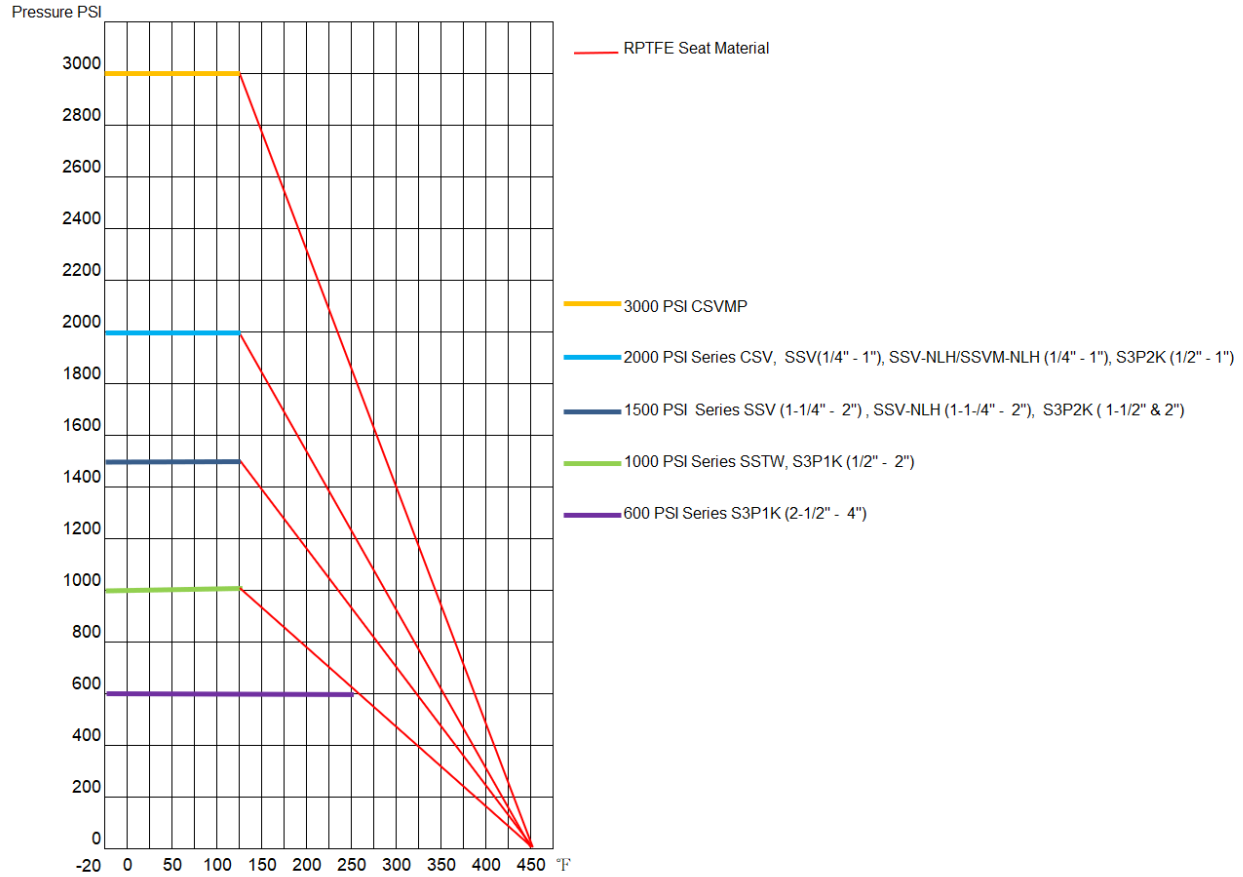

Drawing Date: 8/2022

Rev. Level-Date:

Technical Data