

Nickel-Plated Brass Ball Valves Mini Series


Specifications

- 600 PSI CWP 150 WSP
Vacuum Service Up to 29.9" Hg
- Temperature Range: -4° F to 370° F
- Connection:
DCBV Series (FNPT x FNPT)
DCMV Series (MNPT x FNPT)
- 1/8" - 3/8" Full Port
1/2" Regular Port
- Blow Out Proof Stem
- Construction: One Piece Brass (C3800) Nickel-Plated Body
- Chrome-Plated Brass Ball
- PTFE Double Ball Seats Allow Valve to be Operated in Either Direction and Double Viton® O-Rings Allow for Higher Operating Pressure
- Handle: Zinc Metal Wedge Handle


Approvals

- RoHs Compliant Meets
- Meets MSS SP-110 Standards
- ISO Registered Factory

DCBV Series
FNPT x FNPT

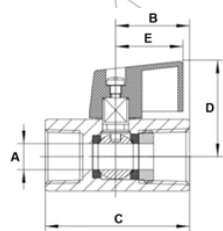

DCMV Series
MNPT x FNPT

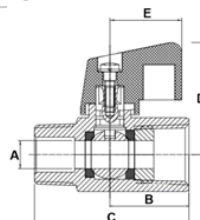


NPT	Model No. FNPT x FNPT	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/8"	DCBV-18	0.236	0.82	1.57	1.26	0.81	6.00	0.27	80
1/4"	DCBV-25	0.315	0.89	1.67	1.26	0.81	8.23	0.26	80
3/8"	DCBV-38	0.315	0.89	1.73	1.26	0.81	8.23	0.28	80
1/2"	DCBV-50	0.393	1.06	2.08	1.26	0.81	15.00	0.35	80

NPT	Model No. MNPT x FNPT	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/8"	DCMV-18	0.236	0.82	1.57	1.26	0.81	6.00	0.22	80
1/4"	DCMV-25	0.315	0.89	1.67	1.26	0.81	8.23	0.23	80
3/8"	DCMV-38	0.315	0.89	1.73	1.26	0.81	8.23	0.23	80
1/2"	DCMV-50	0.393	1.06	2.08	1.26	0.81	15.00	0.26	80



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -4°F to 370°F

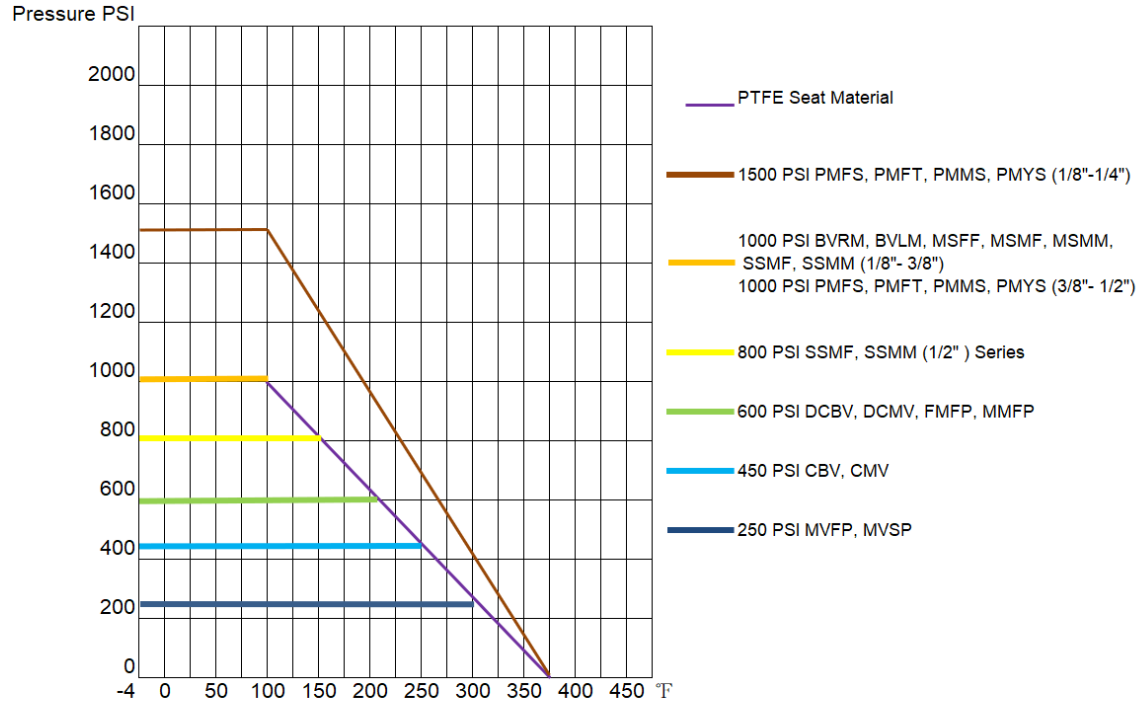

Drawing Date: 8/2022
Rev. Level-Date:

Technical Data