


Hose Barb Fittings

Male Hose Barb 90° Elbow (MPT x Hose)

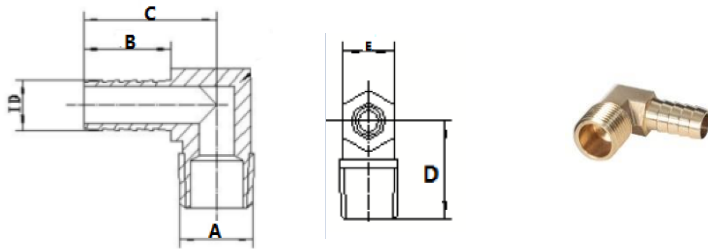

Pressure Rating:150PSI

Temperature Range: -40°F to 160°F

One Piece, Use with Plastic Tubing or Rubber Hose

Intended for Use with Hose Clamps or Crimp Type Ferrule

Barb Size Hose I.D.

Connection: MPT x Hose 90° Elbow

Part No.	Size (In)	ID	A (In)	B (In)	C (In)	D (In)	E (In)
HBE-1825	1/8 x 1/4	1/4"	1/8"	0.87"	1.26"	0.83"	1/2"
HBE-2525	1/4 x 1/4	1/4"	1/4"	0.87"	1.26"	0.83"	1/2"
HBE-2538	1/4 x 3/8	3/8"	1/4"	0.90"	1.26"	0.83"	1/2"
HBE-3838	3/8 x 3/8	3/8"	3/8"	0.90"	1.38"	1.02"	5/8"
HBE-5050	1/2 x 1/2	1/2"	1/2"	0.98"	1.50"	1.10"	11/16"

Drawing Date: 8/2019

Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov