


Hose Barb Fittings
Female Hose Barbs (FPT x Hose)

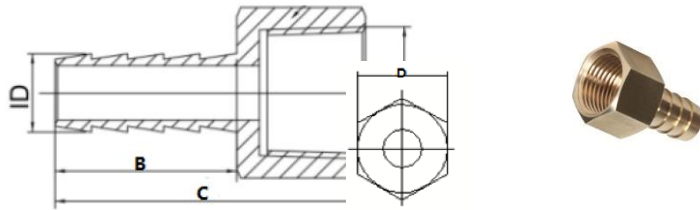

Pressure Rating: 150PSI
Temperature Range: -40°F to 160°F
One Piece, Use with Plastic Tubing or Rubber Hose
Intended for Use with Hose Clamps or Crimp Type Ferrule
Barb Size Hose I.D.
Connection: FPT x Hose

Part No.	Size (In)	ID	A (In)	B (In)	C (In)	D (In)
HBF-1825	1/8 x 1/4	1/4"	1/8"	0.84"	1.37"	1/2"
HBF-2525	1/4 x 1/4	1/4"	1/4"	0.88"	1.43"	5/8"
HBF-2538	1/4 x 3/8	3/8"	1/4"	0.89"	1.43"	5/8"
HBF-3838	3/8 x 3/8	3/8"	3/8"	0.91"	1.55"	3/4"
HBF-5050	1/2 x 1/2	1/2"	1/2"	0.98"	1.66"	15/16"

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov