


Hose Barb Fittings
Male Hose Barbs (MPT x Hose)

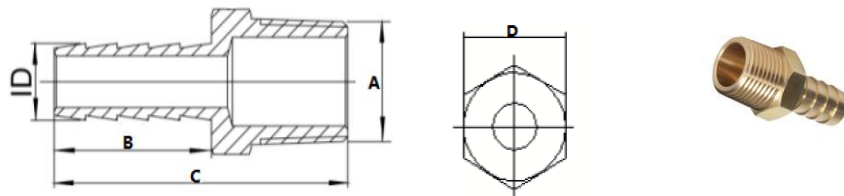

Pressure Rating: 150PSI
Temperature Range: -40°F to 160°F
One Piece, Use with Plastic Tubing or Rubber Hose
Intended for Use with Hose Clamps or Crimp Type Ferrule
Barb Size Hose I.D.
Connection: MPT x Hose

Part No.	Size (In)	ID	A (In)	B (In)	C (In)	D (In)
HBM-1825	1/8 x 1/4	1/4"	1/8"	0.86"	1.46"	7/16"
HBM-2525	1/4 x 1/4	1/4"	1/4"	0.96"	1.70"	9/16"
HBM-2538	1/4 x 3/8	3/8"	1/4"	0.89"	1.57"	9/16"
HBM-3838	3/8 x 3/8	3/8"	3/8"	0.89"	1.65"	11/16"
HBM-5050	1/2 x 1/2	1/2"	1/2"	0.98"	1.97"	7/8"

Drawing Date: 8/2019
Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov