
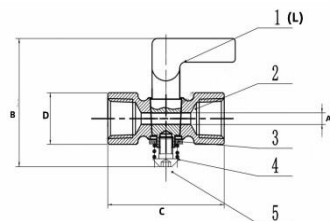


Brass Stop Cock Plug Valve F(NPT)

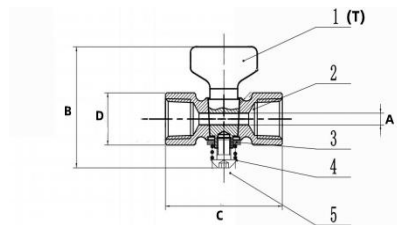

Stop Cock Plug Valves are Ideal for Applications Requiring a Quick On-Off Operation, Which is Accomplished with a Quarter Turn of the Valve Handle
Stop Cock Plug Valves are Compact with a Small Profile

With Inline Maintenance Capabilities, Leak Tight Service and Minimal Resistance to Flow, These Valves are an Excellent Option for Many Commercial and Light Industrial Applications Which Require Directional Flow Control or Low-Pressure

Temperature Range: 35°F to 500°F
Maximum Pressure: 80 psi @500°F

Brass Body and Handle
Standard Port
Connection F(NPT)

T-Handle

MC Part No.	Size	A (In)	B (In)	C (In)	D (In)	Carton Qty	Wt. (lbs.)
MCPV18-FTH	1/8"	0.15	1 1/2"	1 5/8"	0.69	250	0.16
MCPV25-FTH	1/4"	0.15	1 1/2"	1 5/8"	0.69	250	0.14
MCPV38-FTH	3/8"	0.15	1 1/2"	1 7/8"	0.87	150	0.21

Lever Handle

MC Part No.	Size	A (In)	B (In)	C (In)	D (In)	Carton Qty	Wt. (lbs.)
MCPV18-FLVH	1/8"	0.15	1 1/2"	1 5/8"	0.69	250	0.17
MCPV25-FLVH	1/4"	0.15	1 1/2"	1 5/8"	0.69	250	0.15
MCPV38-FLVH	3/8"	0.15	1 1/2"	1 7/8"	0.87	150	0.22
MCPV50-FLVH	1/2"	0.15	1 1/2"	2"	0.98	150	0.22

Weights Are ± 3%

Part No.	Description	Material
1	Handle	Brass
2	Body	Brass
3	Washer	Q235 Carbon Steel
4	Spring	SUS304 Stainless Steel
5	Screw	SUS304 Stainless Steel

Date:10/2022
Rev Level-Date:R1 1/2023



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov