


Brass Ball Valves Mini Series

Specifications

- 600 PSI CWP 150 WSP (FMFP, MMFP Series)
1000 PSI CWP 150 WSP (BVLM Series)
Vacuum Service Up to 29.9" Hg
- Temperature Range: -4° F to 370 ° F
- Connection:
FMFP Series (FNPT x FNPT)
MMFP Series (MNPT x FNPT)
BVLM Series (MNPT x MNPT)
BLVM-Y Series (OD x OD)
- Full Port
- PTFE Ball Seat and Viton® O-Ring
- Blow Out Proof Stem
- Construction:
Brass Extruded Bar (FMFP Series, MMFP Series)
2-Piece Brass Body and Cap (BVLM Series, BLVM-Y Series)
- Chrome-Plated Brass Ball
- Handle: Steel Nickel-Plated

Approvals

- RoHs Compliant
- Meets MSS SP-110 Standards
- ISO Registered Factory

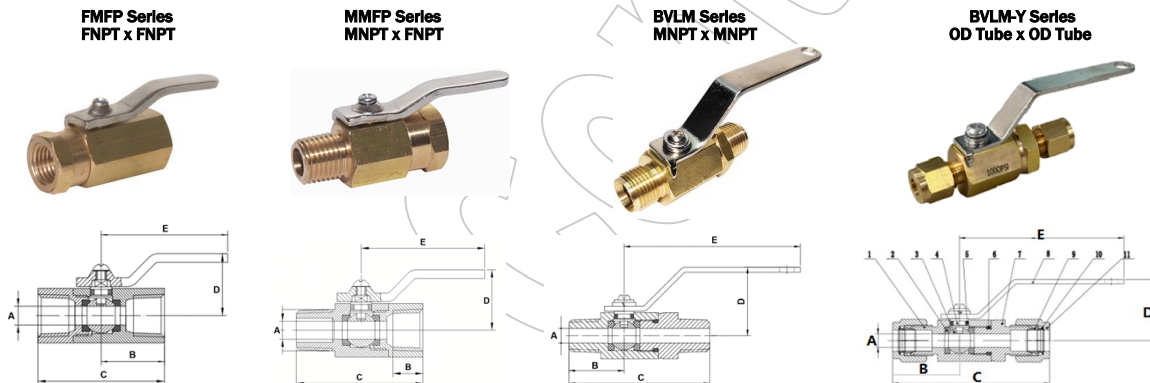

NPT	Model No. 600 PSI FNPT x FNPT	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/4"	FMFP-25	0.23	0.81	1.61	0.78	1.61	8.23	0.15	250

NPT	Model No. 600 PSI MNPT x FNPT	Hex	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/8"	MMFP-18	0.68	0.236	0.83	1.65	0.78	1.61	6.00	0.13	250
1/4"	MMFP-25	0.68	0.236	0.83	1.65	0.78	1.61	8.23	0.13	250


NPT	Model No. 1000 PSI MNPT x MNPT	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/4"	BVLM-25M	0.24	0.88	2.26	1.11	2.83	8.23	0.22	80

NPT	Model No. 1000 PSI OD x OD	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/8"	BLVM-18Y	0.13	0.94	2.40	1.11	2.83	2.83	0.22	80
1/4"	BVLM-25Y	0.25	1.01	2.59	1.11	2.83	8.23	0.22	80



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -4°F to 370°F

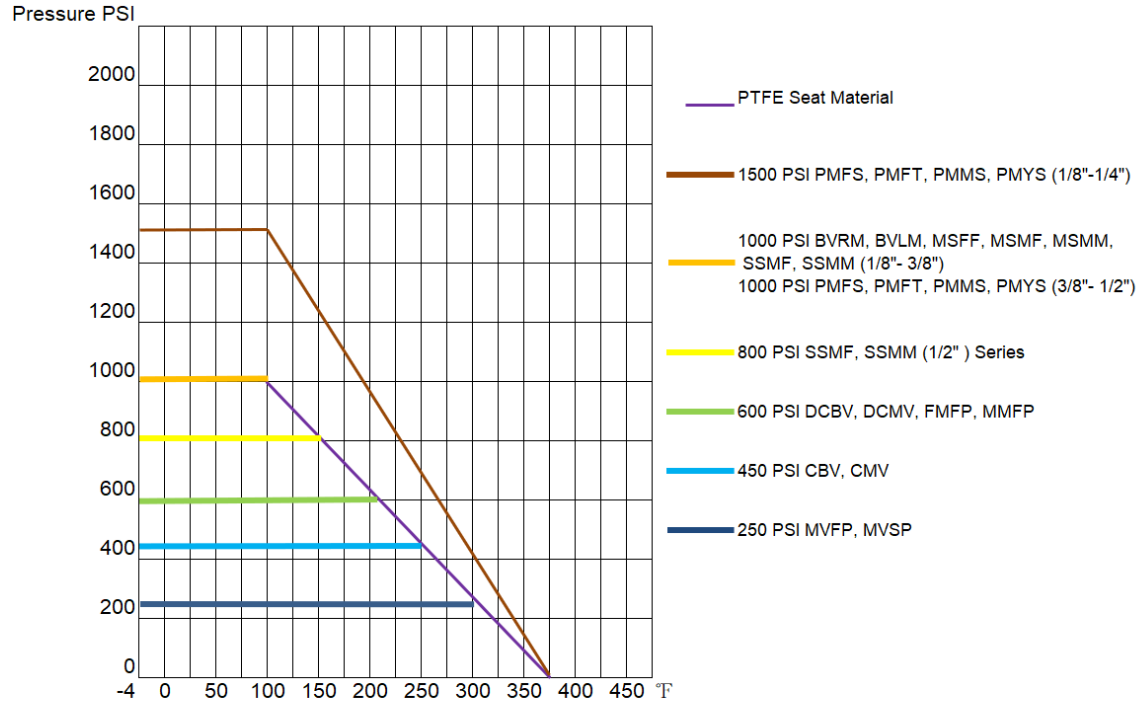

Drawing Date: 8/2022
Rev. Level-Date:

Technical Data