
 
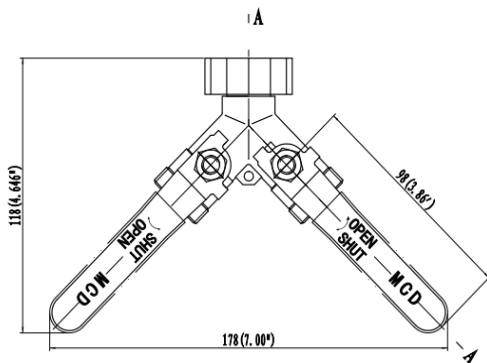


MTWG-7575 Garden Hose Connection Valve with Lever Handle



Weight: .90 lbs.

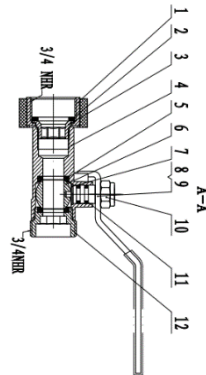

145 PSI CWP Service
Temperature Range :32 F to 200 F
Forged Brass Construction
Blow Out Proof Stem
Chrome-Plated Brass Ball
PTFE Ball Seats and NBR O-Ring
3/4 NH FPT Inlet
3/4 NH MPT Outlets (2)

Part No.	Description	Material
1	Hand Wheel	Brass/Rubber
2	Gasket	NBR
3	Cap	Brass
4	Body	Brass
5	Ball Seats	PTFE
6	Ball	Brass Chrome Plated
7	Stem	Brass
8,9	Handle	Zinc Cast/Rubber
10	Nut	A2-70
11	O-ring	NBR
12	Cap	Brass

Drawing Date: 5/2009

Rev. Level-Date: R1 8/2020



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov