


Load Genie

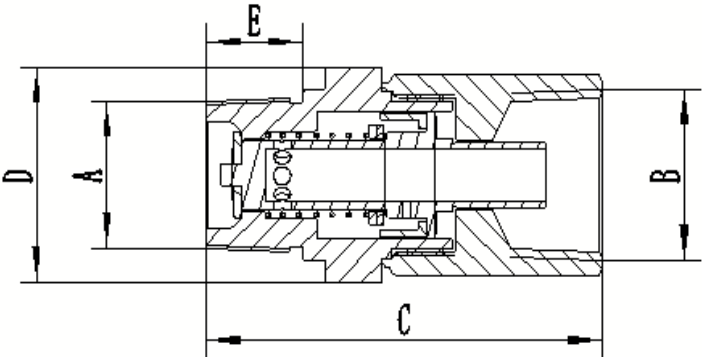

Minimum opening pressure: 2 PSI
Maximum Pressure: 250 PSI
Thread adhesive: Loctite 516 red
Flow Range Free Air(CFM): 1 to 6
Maximum Temperature 450°F
Mounting: Vertical or Horizontal
Application: For Small Air Compressors

Part No.	A (In)	B (In)	C (In)	D (In)	E (In)	Wt. (lbs.)
PA-7575	3/4NPT	3/4NPT	2.65	HEX 1.29	0.56	0.58
PA-3838	3/8NPT	3/8NPT	1.82	HEX 0.81	0.44	0.18
PA-2525	1/4NPT	1/4NPT	1.71	HEX 0.75	0.43	0.15
PA-5050	1/2NPT	1/2NPT	2.251	HEX 1.00	0.43	0.50

Weights Are ± 3%

Description	Material
Retaining ring	s.s.
Washer	Viton
Body	Brass
Spring	Steel
Stem	Brass
Washer	Viton
Washer	Brass
Washer	Brass
Retaining ring	PTFE
Washer	PI reinforced PTFE
Retaining ring	s.s.
Cap	Brass



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov

Drawing Date: 11/30/2023
Rev Level-Date: R2