


3-Way Panel Mount Brass Ball Valves

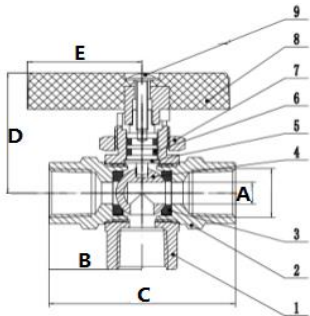

1500 PSI CWP 150 WSP for 1/8" to 1/4"
1000 PSI CWP 150 WSP for Bottom
Port on 3/8" to 1/2"
600 PSI CWP for Side Port on 3/8" and 1/2"
1/8" to 3/8" Full Port , 1/2" Standard Port
Suitable for Vacuum Service to 29.9"Hg
Temperature Range: -4°F to 370°F
Panel-Mount Hole is 9/16" Dia
Brass Body and Cap
PTFE Ball Seat
Viton® Stem Sealing
Chrome-Plated Brass Ball
Zinc Wedge Handle
FPT Connection
ISO Registered Factory
Meets MSS SP-110 Standards
RoHS Compliant

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Cv	Wt. (lbs.)	Carton Qty
PMFT-18	1/8"	0.24	0.95	1.89	1.30	1.18	6.00	0.18	78
PMFT-25	1/4"	0.31	0.95	1.89	1.30	1.18	8.23	0.34	48
PMFT-38	3/8"	0.39	1.07	2.13	1.42	1.54	8.23	0.55	18
PMFT-50	1/2"	0.39	1.31	2.60	1.50	1.54	15.00	0.94	12

Weights Are ± 3%

Part No.	Description	Material
1	Body	Brass
2	Cap	Brass
3	Seat	PTFE
4	Ball	Chrome-Plated Brass
5	Stem	Brass
6	Stem Seal	Viton®
7	Hex Nut	Brass
8	Handle	Zinc Alloy
9	Screw	S.S

Drawing Date: 10/2018
Rev. Level-Date: R3 9/2022



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov