


Mini Brass Ball Valves w/Wedge Handle

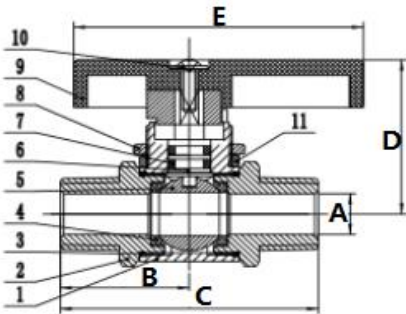

1500 PSI CWP 150 WSP for 1/8" to 1/4"
1000 PSI CWP 150 WSP for 3/8" to 1/2"
Suitable for Vacuum Service to 29.9"Hg
1/8" to 3/8" Full Port , 1/2" Standard Port
Temperature Range: -4°F to 370°F
Panel-Mount Hole is 9/16" Dia
Brass Body and Cap
PTFE Ball Seat
NBR Stem Sealing
Chrome-Plated Brass Ball
Zinc Wedge Handle
MPT Connection
ISO Registered Factory
Meets MSS SP-110 Standards
RoHS Compliant

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Cv	Wt. (lbs.)	Carton Qty
PMMS-18	1/8"	0.24	0.95	1.88	1.30	1.95	6.00	0.16	78
PMMS-25	1/4"	0.31	0.95	1.88	1.30	2.05	8.23	0.32	36
PMMS-38	3/8"	0.39	1.11	2.22	1.42	2.51	8.23	0.52	24
PMMS-50	1/2"	0.39	1.19	2.37	1.50	2.70	15.00	0.70	18

Weights Are ± 3%

Part No.	Description	Material
1	Body	Brass
2	Cap	Brass
3	Seat	PTFE
4	Ball	Chrome-Plated Brass
5	Stem	Brass
6	Stem Seal	NBR
7	Handle	Zinc Alloy
8	Screw	Brass
9	Hex Nut	Brass

Drawing Date: 10/2018
Rev. Level-Date: R3 9/2022



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov