


SPMFF-25 2-Way Brass Panel Mount Ball Valve

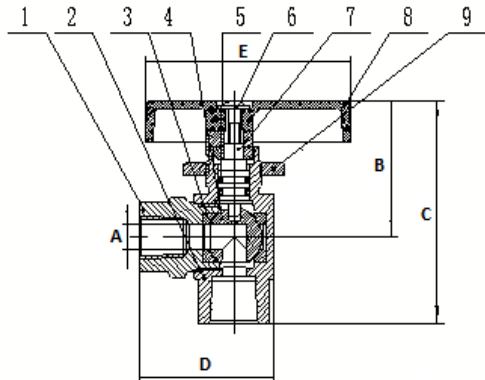

1500 PSI CWP 150 WSP
Suitable for Vacuum Service Up to 29.92" Hg
Full Port
Working Temperature: -40 F to +300 F
Brass Construction
Blow Out Proof Stem
Chrome-Plated Brass Ball
PTFE Ball Seat and Viton® O-Ring
Brass Stem
Zinc Alloy Wedge Handle
Panel-Mount Hole is 9/16" Dia.
1/4" FPT Connection
ISO Registered Factory
MSS SP-110 Approved
RoHS Compliant

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Wt. (lbs.)	Carton Qty
SPMFF-25	1/4"	0.24	1.29"	2.11	1.34	2.05	0.24	120

Part No.	Description	Material
1	Body	Brass
2	Caps	Brass
3	Ball Seats	PTFE
4	Ball	Brass Chrome Plated
5	O-Ring	Viton®
6	Screw	SS304
7	Stem	Brass
8	Handle	Zinc Alloy
9	Nut	Brass



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov

Drawing Date: 7/2017
Rev. Level-Date: R1 8/2020