


316 Stainless Steel Ball Valves 2-Piece

Specifications

- 600 PSI CWP 150 WSP (SSF Series)
1000 PSI CWP 150 WSP (SSR Series)
Vacuum Service Up to 29.9" Hg
- Temperature Range: -20 °F to 425 °F
- Connection: FNPT x FNPT
- Full Port
- PTFE Ball Seat and Packing
- Blow Out Proof Stem
- Construction: 2-Piece 316 Stainless Steel
- Mounting Pad 10-24 UNC Thread (SSR Series)
- 316 Stainless Steel Ball
- Handle: 304 Stainless Steel/Vinyl Grip

Approvals

- RoHs Compliant
- Meets MSS SP-110 Standards
- ISO Registered Factory

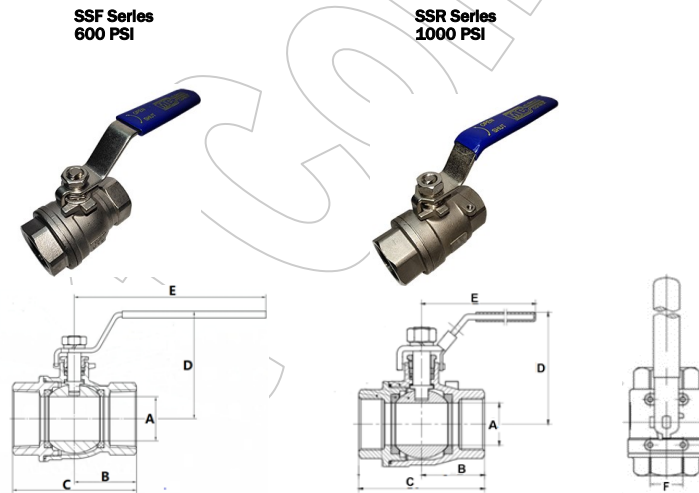


NPT	Model No 600 PSI	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/2"	SSF-50	0.59	0.30	2.24	2.00	3.74	18.55	0.55	40
3/4"	SSF-75	0.77	0.39	2.53	2.24	4.13	29.76	0.78	40
1"	SSF-100	0.98	0.49	3.11	2.75	4.72	51.55	1.29	30
1-1/4"	SSF-125	1.26	0.63	3.56	3.07	5.51	84.42	2.00	16
1-1/2"	SSF-150	1.50	0.75	3.85	3.34	5.70	131.93	2.97	12
2"	SSF-200	1.95	0.98	4.58	4.05	6.69	200.34	4.33	8

NPT	Model No 1000 PSI	A (in)	B (in)	C (in)	D (in)	E (in)	F (in)	CV	Wt. (lbs.)	Carton Qty
1/4"	SSR-25	0.41	1.08	2.15	1.89	3.94	1.12	8.23	0.50	80
3/8"	SSR-38	0.49	1.08	2.15	1.89	3.94	1.12	8.23	0.54	70
1/2"	SSR-50	0.59	1.25	2.50	2.28	4.33	1.14	18.55	0.79	48
3/4"	SSR-75	0.79	1.47	2.94	2.46	4.72	1.38	29.76	1.10	30
1"	SSR-100	0.98	1.74	3.47	2.90	5.81	1.38	51.55	1.94	20



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -20° F to 425° F

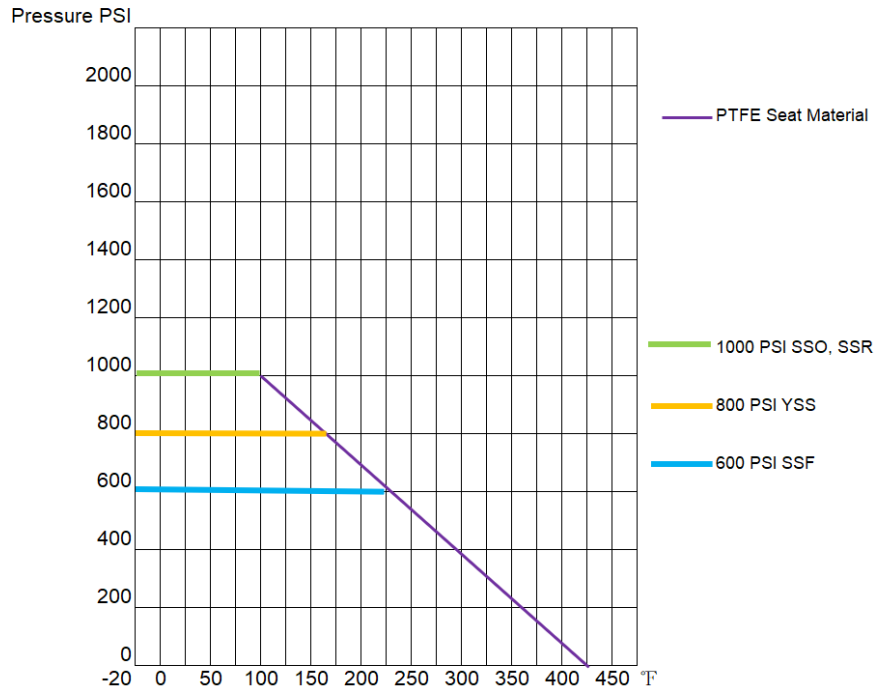

Drawing Date: 8/2022
Rev. Level-Date:

Technical Data