

316 Stainless Steel Ball Valves 2-Piece


Specifications

- 1000 PSI CWP 150 WSP
Vacuum Service Up to 29.9" Hg
- Temperature Range: -4° F to 425 ° F
- Connection: FNPT x FNPT
- Full Port
- Includes Mounting Pad
10-24 UNC Thread (1/4" - 1-1/4")
1/4"-20 UNC Thread (1-1/2" - 2")
- PTFE Ball Seat and Packing
- Blow Out Proof Stem
- Construction: 2-Piece 316 Stainless Steel
- 304 Stainless Steel Ball
- Handle: 304 Stainless Steel Oval Locking Handle/Vinyl Grip
Use with 9/32 Lock (Lock Not Included)

Approvals

- RoHs Compliant
- Meets MSS SP-110 Standards
- ISO Registered Factory

**SSO Series
1000 PSI**

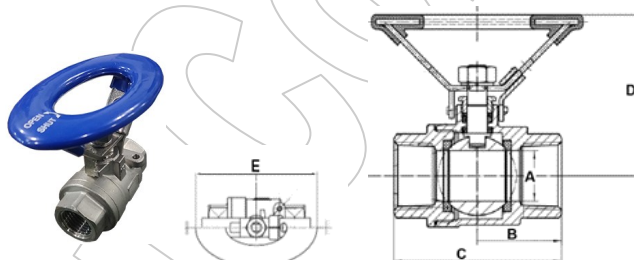


NPT	Model No.	A (in)	B (in)	C (in)	D (in)	E (in)	CV	Wt. (lbs.)	Carton Qty
1/4"	SSO-25V	0.47	1.07	2.13	2.44	3.82	8.23	0.67	40
3/8"	SSO-38V	0.47	1.07	2.13	2.44	3.82	8.23	0.63	40
1/2"	SSO-50V	0.59	1.25	2.50	2.64	3.82	18.55	0.91	40
3/4"	SSO-75V	0.79	1.48	2.95	2.91	3.82	29.76	1.24	30
1	SSO-100V	0.98	1.73	3.46	3.15	4.13	51.55	1.80	10
1-1/4"	SSO-125V	1.26	2.01	4.01	3.46	4.13	84.42	2.78	10
1-1/2"	SSO-150V	1.50	2.17	4.33	4.17	5.35	131.93	3.81	6
2"	SSO-200V	1.93	2.46	4.92	4.53	5.35	200.34	5.57	4



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to

Pressure Temperature Curve -20° F to 425° F

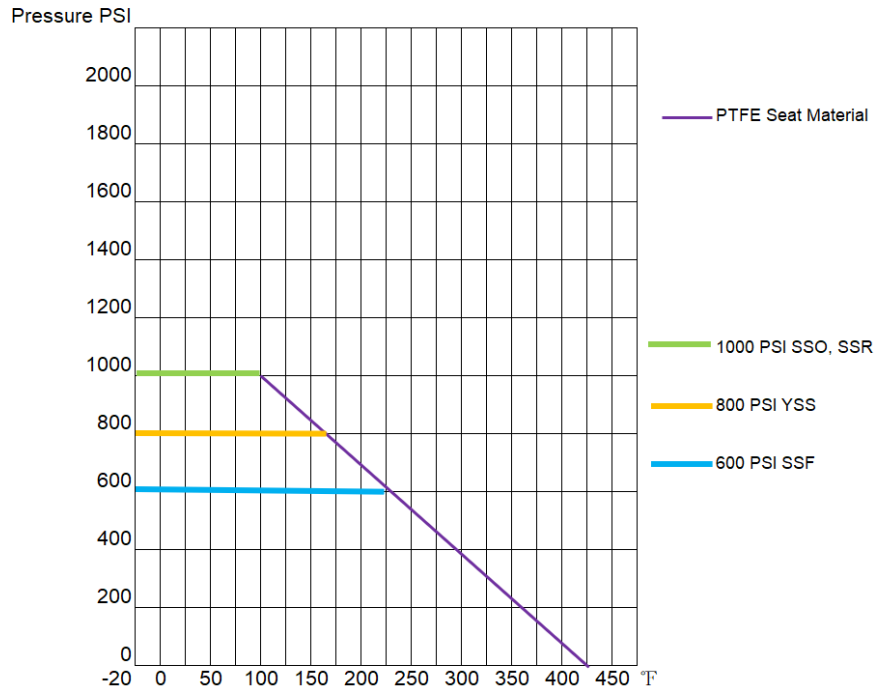

Drawing Date: 8/2022
Rev. Level-Date:

Technical Data