


Industrial Interchange Brass Plugs

Female Plug

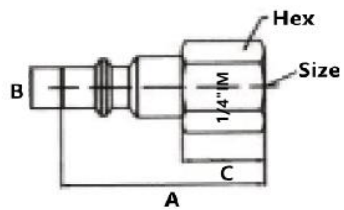

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU1-2PF-J	1/4" FPT	1.46	Ø0.3	0.55	0.63	500	0.04

Industrial Interchange (Type IM) Plugs

Sleeve Pullback Connection Design Provides Strongest Holding Force
Integral Sleeve Guard to Prevent Accidental Disconnection

Brass Construction

300 psi Maximum Working Pressure

1/4" NPT Threads

Stainless Steel Spring and Locking Balls


35 SCFM at 100 psi w/ 10 psi Pressure Drop

Temperature Range: -40 F to 225 F

Meets MIL Spec C-4109F

Accepts 1/4" Industrial Interchange Couplers

Male Plug

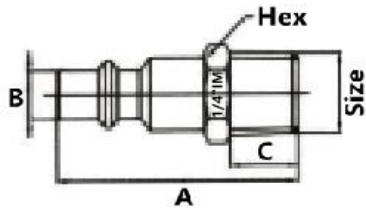

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU1-2PM-J	1/4" MPT	1.52	Ø0.3	0.41	0.55	500	0.05