


Universal Interchange Brass Couplers

Female Coupler

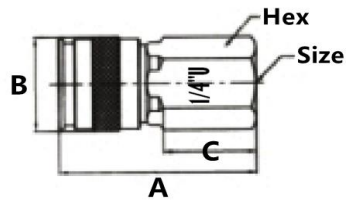

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU18-2SF-J	1/4" FPT	2.09	0.98	1.06	0.79	250	0.18

Universal Interchange Couplers

Quick "Push" Connection Design

Brass Construction

300 psi Maximum Working Pressure

1/4" NPT Threads

Stainless Steel Spring and Locking Balls

35 SCFM at 100 psi w/ 10 psi Pressure Drop


Temperature Range: -40 F to 225 F

Meets MIL Spec C-4109F

Accepts Industrial (Type IM), Automotive (Type T)

and ARO Interchange Plugs

Male Coupler

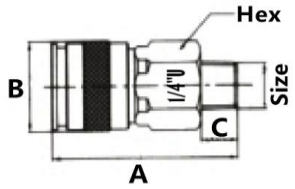

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU18-2SM-J	1/4" MPT	2.09	0.87	0.43	0.79	250	0.17