


Industrial Interchange Steel Plugs

Female Plug

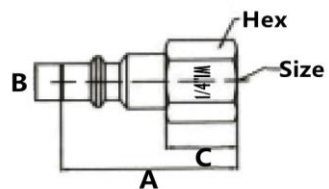

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU3-2PF-J	1/4" FPT	37	Ø7.9	14	16	500	0.05

Industrial Interchange (Type IM) Plugs

Quick "Push" Connection Design

Steel Construction

300 psi Maximum Working Pressure

1/4" NPT Threads

Zinc Plated Stainless Steel Spring


35 SCFM at 100 psi w/ 10 psi Pressure Drop

Temperature Range: -40 F to 225 F

Meets MIL Spec C-4109F

Accepts 1/4" Industrial Interchange Couplers

Male Plug

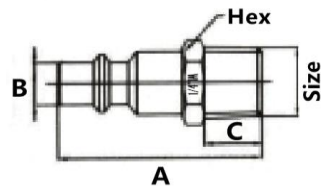

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU3-2PM-J	1/4" MPT	38.5	Ø7.9	10.5	14	500	0.05