


Industrial Interchange Steel Couplers

Female Coupler

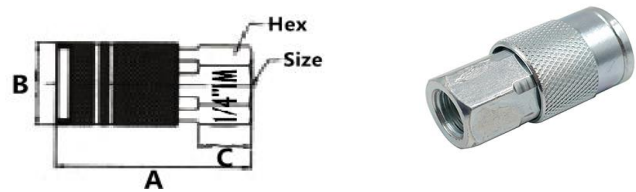

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU3-2SF-J	1/4" FPT	1.81	0.87	0.53	0.75	250	0.18

Industrial Interchange (Type IM) Couplers

Quick "Push" Connection Design

Steel Construction

300 psi Maximum Working Pressure

1/4" NPT Threads

Zinc Plated Stainless Steel Spring


35 SCFM at 100 psi w/ 10 psi Pressure Drop

Temperature Range: -40 F to 225 F

Meets MIL Spec C-4109F

Accepts 1/4" Industrial Interchange Plugs

Male Couplers

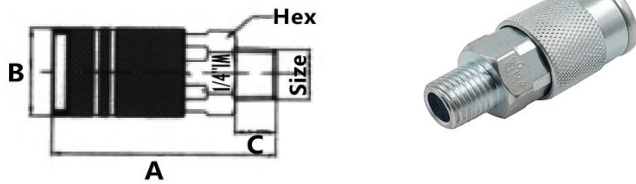

Part No.	Size	A (In)	B (In)	C (In)	Hex (In)	Carton Qty	Wt. (lbs.)
SU3-2SM-J	1/4" MPT	2.10	0.09	0.02	0.07	250	0.18