


SV-18516 Elbow Valve with Schrader Air Release Assembly

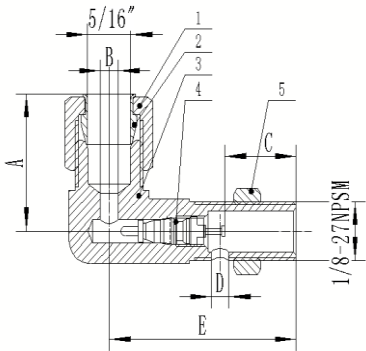

Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating 300 PSI
Temperature Range: -40°F to 250°F

Part No.	Size	A (In)	B (In)	C (In)	D (In)	E (In)	Wt. (lbs.)	Carton Qty
SV-18516	1/8-27NPSM x 5/16 O.D.	0.91	0.13	0.52	0.13	1.38	0.11	500

Weight are ±3%

Part No.	Description	Material
1	Nut	Brass
2	Cap	Brass
3	Fitting	Brass
4	Plug	Brass
5	Nut	Brass

Drawing Date:3/2016
Rev. Level-Date:R3 08/26/2024