


1 Piece 316 Stainless Steel Ball Valve

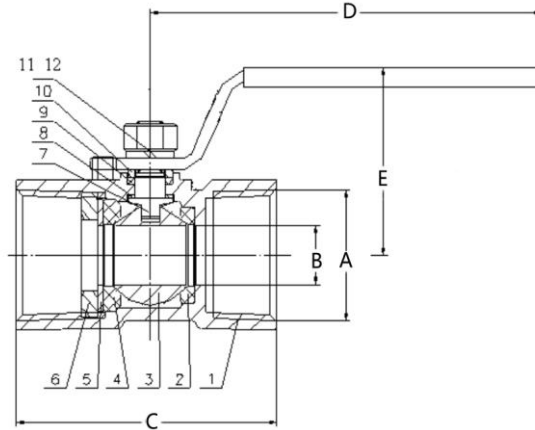

1000 PSI CWP 150 WSP Service
Suitable for Vacuum Service Up to 29"Hg
1/4", 3/8" & 1/2" Regular Port
3/4" - 2" Reduced Port
Temperature Range: -20°F to 425 °F
316 Stainless Steel Construction
Blow Out Proof Stem
316 Stainless Steel Ball and Stem
PTFE Seats and Seals
Lever Handle
Connection: FPT

Part No.	A (Size)	B (In)	C (In)	D (In)	E (In)	Wt. (lbs.)	Carton Qty
SV1P-25	1/4"	0.19"	1.57"	2.75"	1.33"	0.32	80
SV1P-38	3/8"	0.27"	1.77"	2.75"	1.40"	0.47	60
SV1P-50	1/2"	0.35"	2.16"	3.54"	1.53"	0.56	48
SV1P-75	3/4"	0.45"	2.36"	3.54"	1.69"	0.85	36
SV1P-100	1"	0.59"	2.75"	4.13"	1.81"	1.03	24
SV1P-125	1 1/4"	0.77"	3.14"	4.72"	2.08"	1.44	18
SV1P-150	1 1/2"	0.98"	3.38"	5.10"	2.32"	1.93	12
SV1P-200	2"	1.25"	3.98"	5.50"	2.55"	2.94	6

Weights Are ± 3%

Part No.	Description	Material
1	Body	S.S.316
2	Ball Seat	PTFE
3	Ball	S.S.316
4	Ball Seat	PTFE
5	Washer	S.S.304
6	Retainer Nut	S.S.304
7	Stem	S.S.316
8	Bottom Seal	PTFE
9	Up Seal	PTFE
10	Gland	S.S.304
11	Handle	S.S.304 with PVC Grip
12	Nut & Washer	S.S.304



WARNING: This product can expose you to chemicals, including Hexavalent Chromium, which is known to the State of California to cause cancer and reproductive harm.
For more information go to www.P65Warnings.CA.gov