
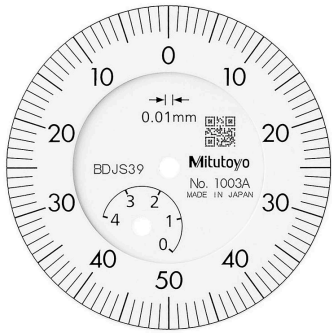


Dial Gauge, Flat Back, ISO Type

Item number: 1003AB

Images

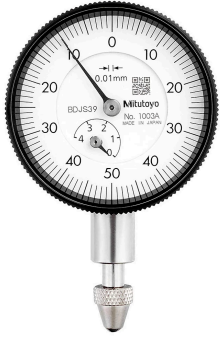

Description

Compact Type, Extra Small Diameter - Metric

This is a compact, dial indicator with a bezel \varnothing 31 / 36 mm. It offers you the following benefits:


- It is ideal for use in applications where space is limited.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Delivered:	With certificate of inspection
Range:	4 mm
Range per rev.:	1 mm
Dial reading:	0-50-0
Graduation:	0.01 mm

MPE any 1/10 revolution:	6 µm
MPE any 1/2 revolution:	9 µm
MPE any 1 revolution:	10 µm
MPE measuring range:	14 µm
H MPE (Hysteresis):	3.5 µm
R MPE (Repeatability):	3 µm
Measuring force:	0,3-1,4 N
Mass:	48 g
Stem:	8 mm
Contact point:	Carbide tipped, thread: M 2.5 x 0.45 mm
Balanced dial:	Yes
Type:	EN ISO Standard

Dimensions

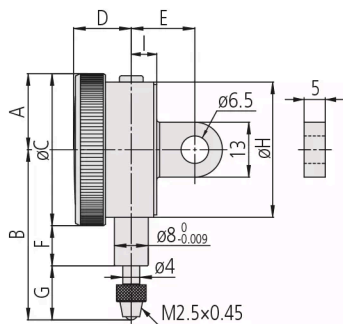

- A:** 18 mm
- B:** 40.3 mm
- C:** 36 mm
- D:** 13.5 mm
- E:** 15 mm
- F:** 9.5 mm
- G:** 12.8 mm
- H:** 32 mm
- I:** 6 mm

Spare parts

Consumable spares:



Contact Element Ball Point, M2,5x0,45

8,3mm Length, Metric
 Art No. 21AZA319
 Suggested retail price: 17.00 €*