


# Outside Micrometer with Cr Finish Frame

Item number: 101-114

## Images

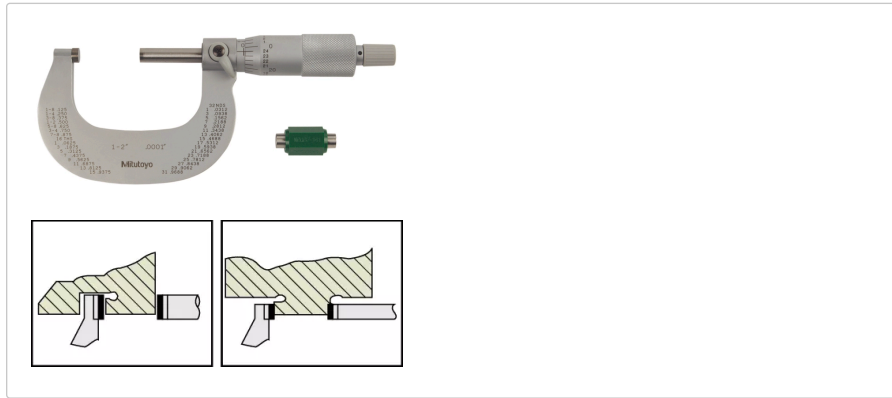

## Description

- Satin-chrome-finished frame, tapered (behind the anvil) for hard-to-reach places.

## Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	1 - 2 "
<b>Graduation:</b>	0.0001"
<b>Max. Permissible Error J MPE:</b>	±0.0001"
<b>Delivered:</b>	Including box, key, setting standard (from 2" upward)
<b>Flatness:</b>	0.000024"
<b>Parallelism:</b>	0.00008"
<b>Remarks:</b>	Ratched Stop
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35$ mm , spindle pitch 0,635 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	245 g

## Dimensions

