

Outside Micrometer with Heat Ins. Plate

Item number: 102-327-10

Images



Description

Cut-away frame behind anvil for measuring in hard to reach places. A ratchet stop or friction thimble guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0-1 "
Graduation:	0,0001"
Max. Permissible Error J MPE:	±0,0001"
Delivered:	Including box, key, certificate of inspection
Flatness:	0,000024"
Parallelism:	0.00008"
Remarks:	Ratched Stop
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish
Mass:	180 g

Accessories

Optional accessories:




Color Ratchet Stop

for Analog Micrometer 0-300 mm Black

Art No. 985056

Suggested retail price: 11.30 €*

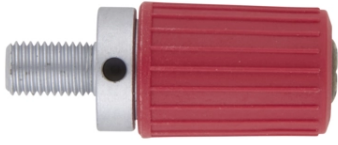

Color Ratchet Stop

for Analog Micrometer 0-300 mm Red
Art No. 985061
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Blue
Art No. 985081
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Yellow
Art No. 985071
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Green
Art No. 985076
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Brown
Art No. 985066
Suggested retail price: 11.30 €*



Micrometer Ratchet Stop Plastic

for Analog Micrometer 0-300 mm, Grey
Art No. 04GZA239
Suggested retail price: 9.50 €*



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
~~Suggested retail price: 70.00 €*~~