


Outside Micrometer with Heat Ins. Plate

Item number: 102-328-10

Images

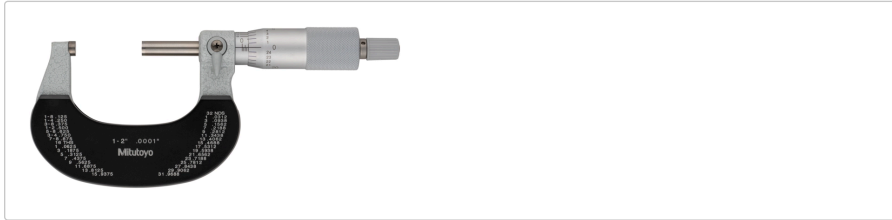

Description

Cut-away frame behind anvil for measuring in hard to reach places. A ratchet stop or friction thimble guarantees repeatable measurement.

Features

| | |
|--------------------------------------|--|
| Digital/Analog: | Analog |
| Inch-Metric: | Inch |
| Range: | 1-2 " |
| Graduation: | 0,0001" |
| Max. Permissible Error J MPE: | ±0,0001" |
| Delivered: | Including box, key setting standard, certificate of inspection |
| Flatness: | 0,000024" |
| Parallelism: | 0.00008" |
| Remarks: | Ratched Stop |
| Measuring face: | Carbide tipped, micro-lap finish |
| Measuring spindle: | With spindle lock, \varnothing 6,35 mm, spindle pitch 0,5 mm |
| Scale: | Thimble and sleeve satin chrome finish |
| Mass: | 270 g |


Accessories

Optional accessories:



Color Ratchet Stop

for Analog Micrometer 0-300 mm Black
Art No. 985056
Suggested retail price: 11.30 €*

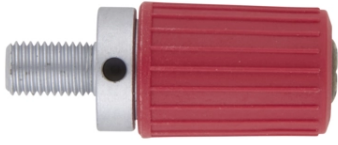

Color Ratchet Stop

for Analog Micrometer 0-300 mm Red
Art No. 985061
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Blue
Art No. 985081
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Yellow
Art No. 985071
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Green
Art No. 985076
Suggested retail price: 11.30 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Brown
Art No. 985066
Suggested retail price: 11.30 €*



Micrometer Ratchet Stop Plastic

for Analog Micrometer 0-300 mm, Grey
Art No. 04GZA239
Suggested retail price: 9.50 €*



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
Promo price: **56.00 €***
~~Suggested retail price: 70.00 €*~~