


Outside Micrometer with Heat Ins. Plate

Item number: 102-332-10

Images

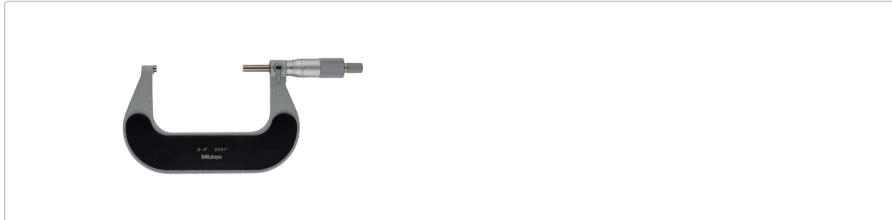

Description

Cut-away frame behind anvil for measuring in hard to reach places. A ratchet stop or friction thimble guarantees repeatable measurement.

Features

Digital/Analog:	Analog
Delivered:	Including box, key setting standard
Inch-Metric:	Inch
Range:	3-4 "
Graduation:	0,0001"
Max. Permissible Error J MPE:	±0.00015"
Flatness:	0,000024"
Parallelism:	0,00012"
Remarks:	Ratched Stop
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø 6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish
Mass:	490 g


Accessories

Optional accessories:



Color Ratchet Stop

for Analog Micrometer 0-300 mm Black
Art No. 985056
Suggested retail price: 15.00 €*

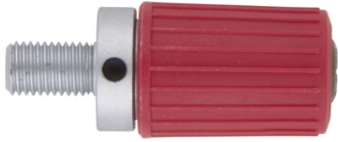

Color Ratchet Stop

for Analog Micrometer 0-300 mm Red
Art No. 985061
Suggested retail price: 15.00 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Blue
Art No. 985081
Suggested retail price: 15.00 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Yellow
Art No. 985071
Suggested retail price: 15.00 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Green
Art No. 985076
Suggested retail price: 15.00 €*



Color Ratchet Stop

for Analog Micrometer 0-300 mm Brown
Art No. 985066
Suggested retail price: 15.00 €*



Micrometer Ratchet Stop Plastic

for Analog Micrometer 0-300 mm, Grey
Art No. 04GZA239
Suggested retail price: 12.00 €*



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
