


Contact Point for Serie 526

Item number: 102474

Images

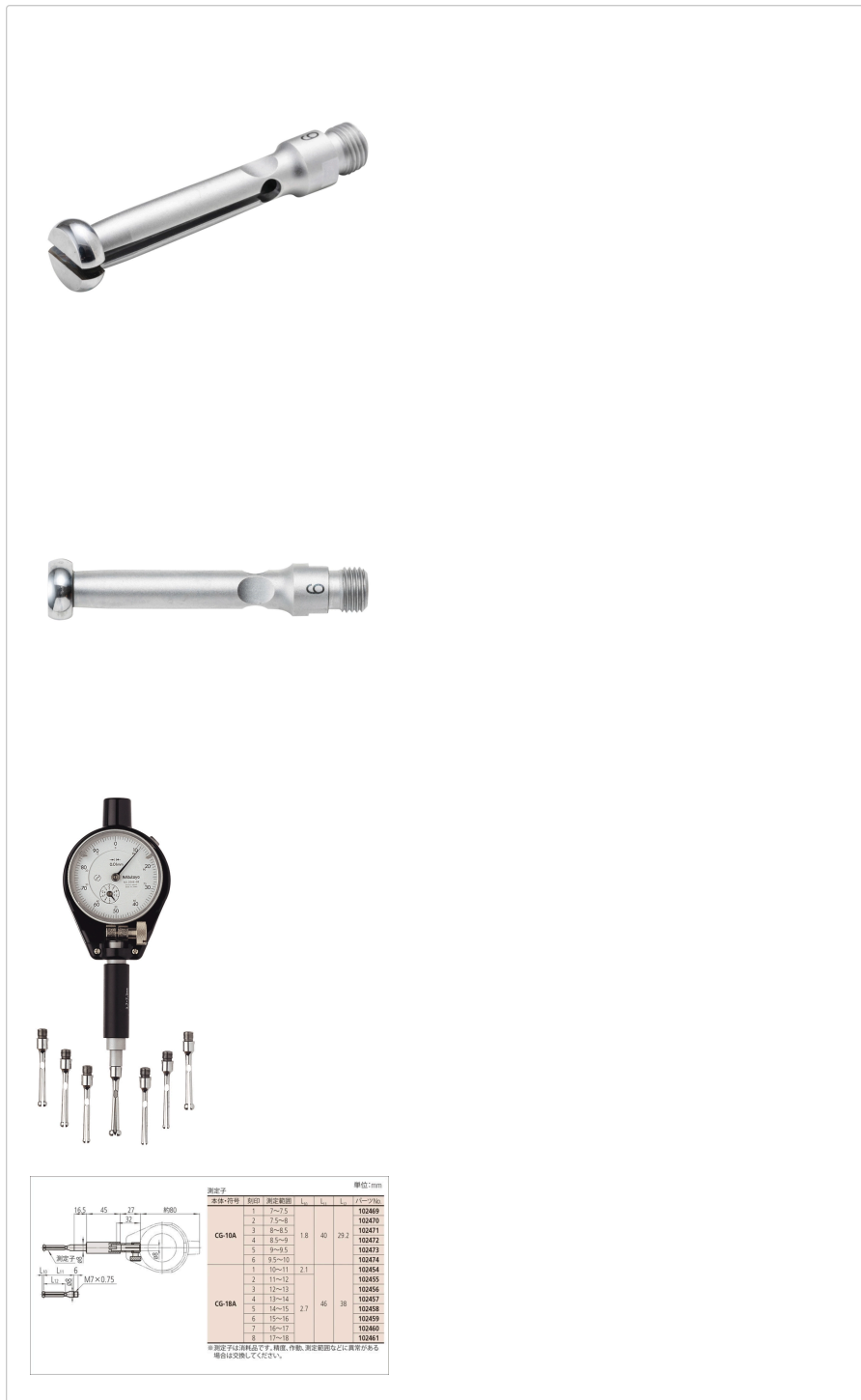

Description

Split-ball probes 0,95-1,15 mm up to 6,7-7,3 mm range are protected by a diamond-like DLC coating.

Split-ball probes 7-18 mm are hard chrome plated

DLC Black Diamond:

- Extremely high wear protection, due to low frictional resistance
- Safety due to high hardness and resistance
- Safety due to sustained accuracy and precision

Features


Range: 9.5 - 10 mm

Marking on the measuring head (engraved): 6

Remarks:

for 526-124-20, 526-126-20

Dimensions

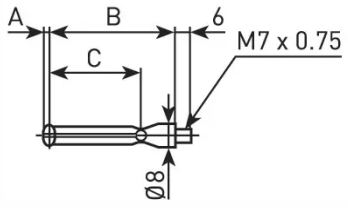

A: 1.8 mm

B: 40 mm

C: 29.2 mm