

## Outside Micrometer Economy Design

Item number: 103-129

### Images




### Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement. High resolution provided by a vernier scale on sleeve.

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	0-25 mm
<b>Graduation:</b>	0,001 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 2 \mu\text{m}$
<b>Delivered:</b>	Including box, key, certificate of inspection
<b>Flatness:</b>	0,6 $\mu\text{m}$
<b>Parallelism:</b>	2 $\mu\text{m}$
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35 \text{ mm}$ ( $\leq 300 \text{ mm}$ ) $\varnothing 8 \text{ mm}$ ( $> 300 \text{ mm}$ ) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	175 g

### Dimensions

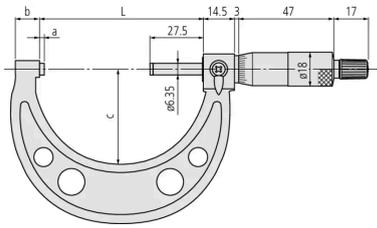

**L:** 30.3 mm

**a:** 2.8 mm

**b:** 9 mm

**c:** 28 mm

## Accessories

Optional accessories:



### Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: **58.00 €\***

Promotion!



### Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €\***

Suggested retail price: **70.00 €\***