

Outside Micrometer Economy Design

Item number: 103-131

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement. High resolution provided by a vernier scale on sleeve.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	0 - 1 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, key, certificate of inspection
Flatness:	0.000024"
Parallelism:	0.00008"
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	175 g

Dimensions

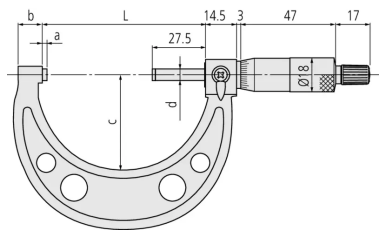

L: 30.3 mm

a: 2,5 mm

b: 9 mm

c: 28 mm

d: 6,35 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: **58.00 €***

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~