


Outside Micrometer Economy Design

Item number: 103-136

Images

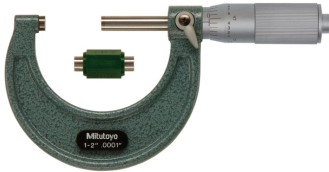


Description

A basic, cost effective, non-digital Mitutoyo micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	1 - 2 "
Graduation:	0.0001"
Max. Permissible Error J MPE:	±0.0001"
Delivered:	Including box, key, setting standard, certificate of inspection
Flatness:	0,000024"
Parallelism:	0.00008"
Remarks:	With friction thimble
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	215 g

Dimensions

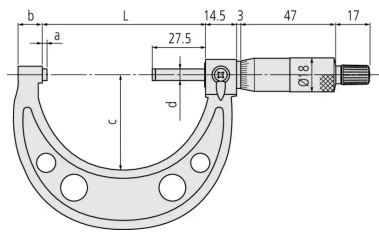

L: 55.3 mm

a: 2,5 mm

b: 10 mm

c: 38 mm

d: 6,35 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: **58.00 €***

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: ~~70.00 €*~~

Standard accessories:



Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: **33.00 €***