

Outside Micrometer Economy Design

Item number: 103-137

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	0-25 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 2 \mu\text{m}$
Delivered:	Including box, key, certificate of inspection
Flatness:	$0,6 \mu\text{m}$
Parallelism:	$2 \mu\text{m}$
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$), spindle pitch $0,5 \text{ mm}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring force:	5 - 10 N
Mass:	175 g

Dimensions

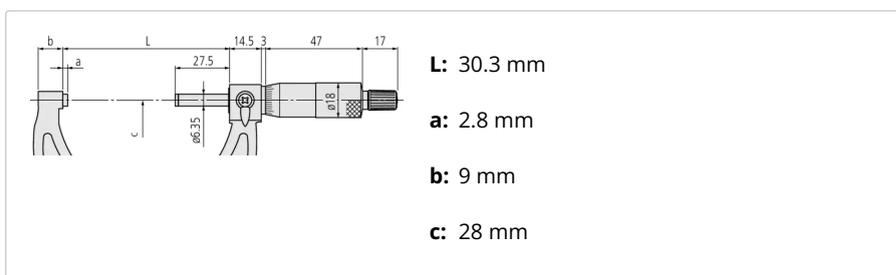

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"
Art No. 156-105-10
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"
Art No. 156-101-10
**Promo price: 56.00 €*
Suggested retail price: 70.00 €***