

Outside Micrometer Economy Design

Item number: 103-138

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	25-50 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±2 µm
Delivered:	Including box, key, setting standard, certificate of inspection
Flatness:	0,6 µm
Parallelism:	2 µm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	215 g

Dimensions

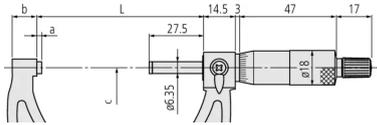

L: 55.3 mm

a: 2.8 mm

b: 10 mm

c: 38 mm

Accessories

Optional accessories:



Micrometer Stand, 45° Angle Type

for Micrometer 0-50mm/0-2"

Art No. 156-105-10

Suggested retail price: 58.00 €*

Promotion!



Micrometer Stand, Adjustable Angle Type

for Micrometer 0-100mm/0-4"

Art No. 156-101-10

Promo price: **56.00 €***

Suggested retail price: 70.00 €*

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: 33.00 €*