

Outside Micrometer Economy Design

Item number: 103-141-10

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	100-125 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 3 \mu\text{m}$
Delivered:	Including box, key, setting standard
Flatness:	$0,6 \mu\text{m}$
Parallelism:	$3 \mu\text{m}$
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch $0,5 \text{ mm}$
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring force:	5 - 10 N
Mass:	515 g

Dimensions

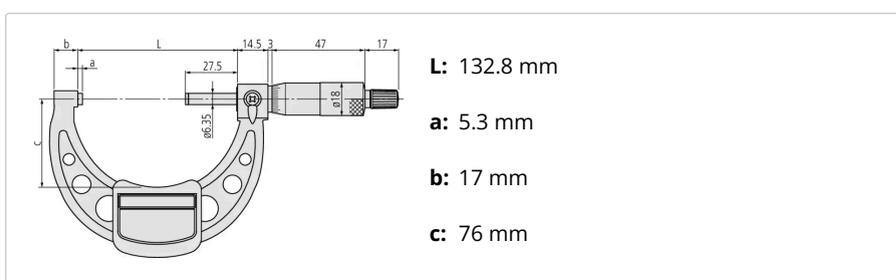

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 100-300mm/5-12"

Art No. 156-102

Suggested retail price: 699.00 €*
*including 19% VAT

Standard accessories:



Micrometer Setting Standard

Length: 100mm

Art No. 167-104

Suggested retail price: 38.00 €*
*including 19% VAT