

Outside Micrometer Economy Design

Item number: 103-143-10

Images




Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	150-175 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 4 \mu\text{m}$
Delivered:	Including box, key, setting standard
Flatness:	$0,6 \mu\text{m}$
Parallelism:	$3 \mu\text{m}$
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 18 \text{ mm}$
Measuring force:	5 - 10 N
Mass:	720 g

Dimensions

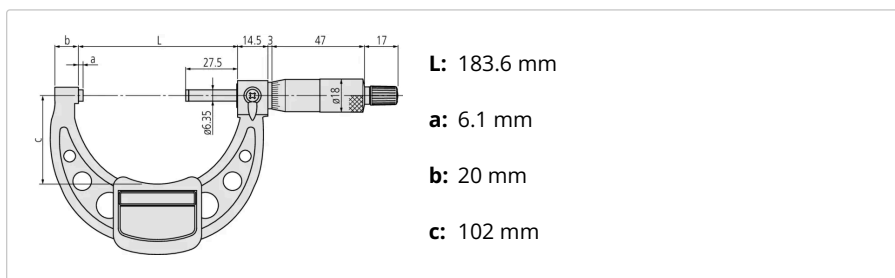

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 100-300mm/5-12"

Art No. 156-102

Suggested retail price: 699.00 €*
*incl. VAT

Standard accessories:



Micrometer Setting Standard

Length: 150mm

Art No. 167-106

Suggested retail price: 43.00 €*
*incl. VAT