

Outside Micrometer Economy Design

Item number: 103-148-10

Images




Description

A basic, cost effective, non-digital Mitutoyo micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	275-300 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±5 µm
Flatness:	0,6 µm
Parallelism:	5 µm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Measuring force:	5 - 10 N
Mass:	1565 g

Dimensions

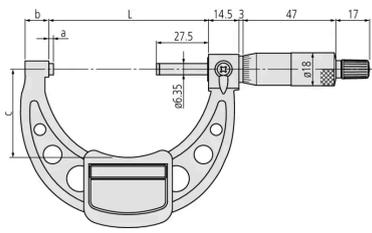

L: 309 mm

a: 6.5 mm

b: 18 mm

c: 166 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 100-300mm/5-12"

Art No. 156-102

Suggested retail price: 632.00 €*

Standard accessories:



Micrometer Setting Standard

Length: 275mm

Art No. 167-111

Suggested retail price: 69.00 €*