


Outside Micrometer Economy Design

Item number: 103-156

Images

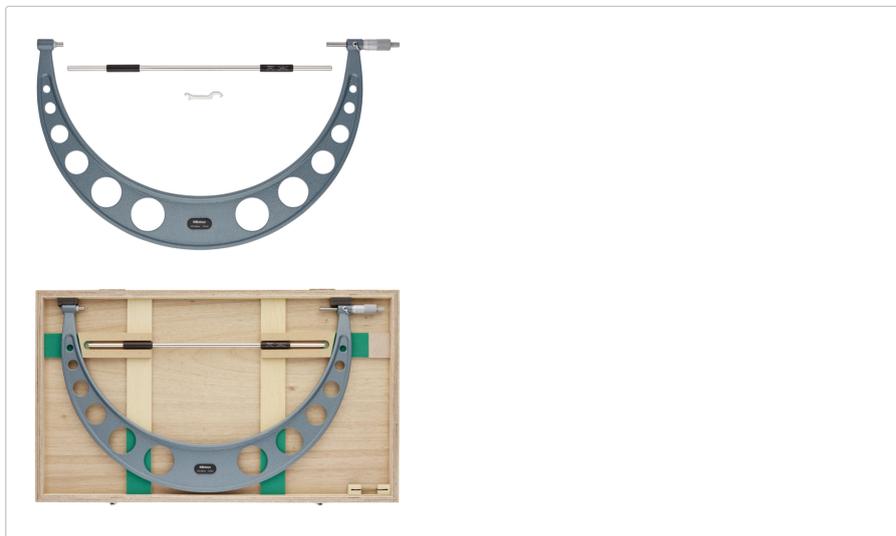


Description

A Mitutoyo basic, cost effective, non-digital micrometer with a ratchet stop to guarantee repeatable measurement.

Features

Model:	OM-500
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	475-500 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	±8 μm
Flatness:	1 μm
Parallelism:	7 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, ø6,35 mm (≤300 mm) ø 8 mm (>300 mm) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø21 mm
Measuring force:	10 - 15 N
Mass:	3450 g

 Dimensions



L: 528 mm

a: 18 mm

b: 28 mm

c: 273 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: **1,183.00 €***

Standard accessories:



Micrometer Setting Standard

Length: 475mm

Art No. 167-119

Suggested retail price: **149.00 €***