


## Outside Micrometer Economy Design

Item number: 103-157

### Images

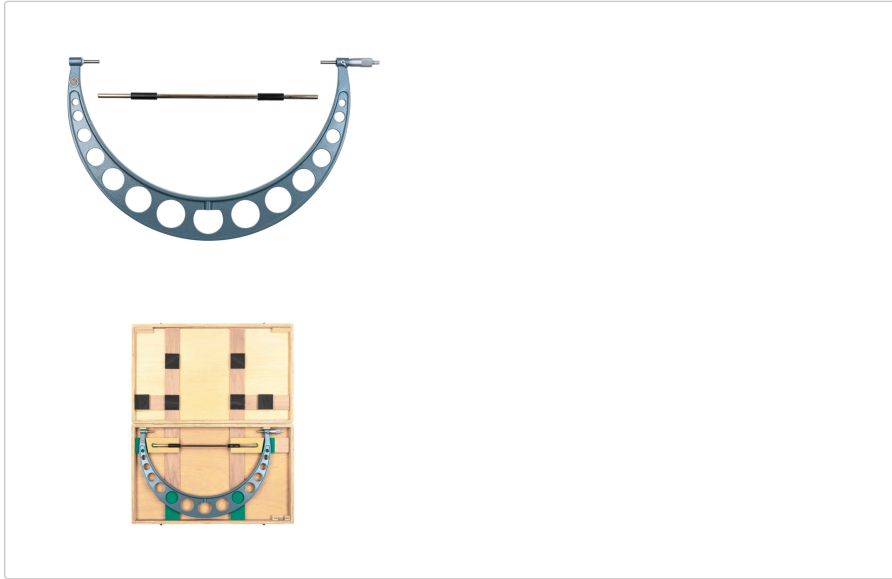

### Description

 
Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

### Features

<b>Model:</b>	OM-525
<b>Digital/Analog:</b>	Analog
<b>Delivered:</b>	Including box, key, setting standard
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	500-525 mm
<b>Graduation:</b>	0,01 mm
<b>Max. Permissible Error J MPE:</b>	$\pm 9 \mu\text{m}$
<b>Flatness:</b>	1 $\mu\text{m}$
<b>Parallelism:</b>	7 $\mu\text{m}$
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish
<b>Measuring spindle:</b>	With spindle lock, $\varnothing 6,35 \text{ mm}$ ( $\leq 300 \text{ mm}$ ) $\varnothing 8 \text{ mm}$ ( $> 300 \text{ mm}$ ) , spindle pitch 0,5 mm
<b>Scale:</b>	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
<b>Measuring force:</b>	10 - 15 N
<b>Mass:</b>	4060 g

### Dimensions



**L:** 575 mm

**a:** 40 mm

**b:** 28 mm

**c:** 307 mm

## Accessories

### Optional accessories:



### Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: **1,183.00 €\***

### Standard accessories:



### Micrometer Setting Standard

Length: 500mm

Art No. 167-120

Suggested retail price: **159.00 €\***