


Outside Micrometer Economy Design

Item number: 103-158

Images

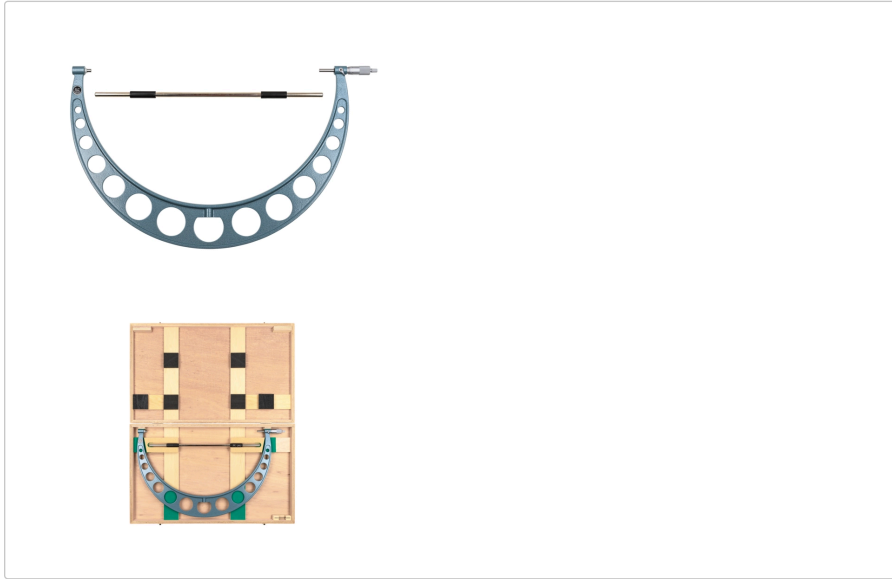

Description


Lightweight workshop design with baked-enamel-finished frame.

- Equipped with Ratchet Stop for constant measuring force.

Features

Model:	OM-550
Digital/Analog:	Analog
Delivered:	Including box, key, setting standard
Inch-Metric:	Metric
Range:	525-550 mm
Graduation:	0,01 mm
Max. Permissible Error J MPE:	$\pm 9 \mu\text{m}$
Flatness:	1 μm
Parallelism:	7 μm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	With spindle lock, $\varnothing 6,35 \text{ mm}$ ($\leq 300 \text{ mm}$) $\varnothing 8 \text{ mm}$ ($> 300 \text{ mm}$) , spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, $\varnothing 21 \text{ mm}$
Measuring force:	10 - 15 N
Mass:	4080 g

 Dimensions



L: 575 mm

a: 15 mm

b: 28 mm

c: 307 mm

Accessories

Optional accessories:



Micrometer Stand

for Micrometer 300-1000mm/12-40"

Art No. 156-103

Suggested retail price: **1,183.00 €***

Standard accessories:



Micrometer Setting Standard

Length: 525mm

Art No. 167-121

Suggested retail price: **171.00 €***